
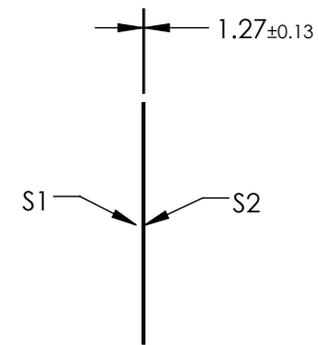
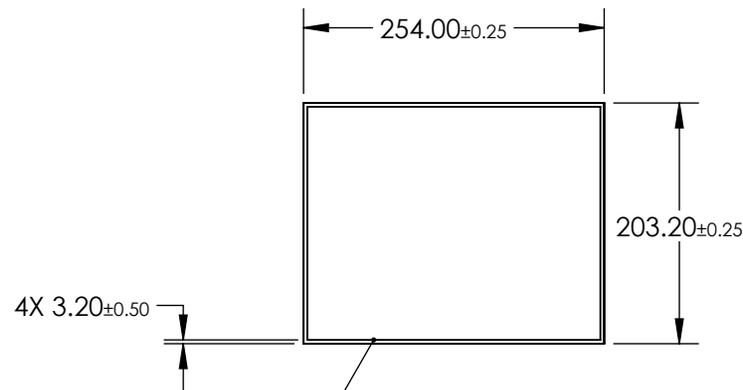


NOTES:

1. SUBSTRATE:
PET
2. COATING (APPLY ACROSS CLEAR APERTURE)
S1: Ravg <1% @450 - 650nm
S2: CLEAR HARD COATED
3. RoHS COMPLIANT

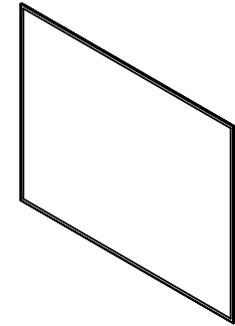

SILVER CONDUCTIVE "L" BUSS
TO REAR, ALL AROUND

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

	S1	S2
SHAPE	PLANO	PLANO
WAVELENGTH RANGE	450 - 650nm	450 - 650nm
SURFACE RESISTIVITY (Ω/Sq)	8	8
BEVEL	PROTECTIVE AS NEEDED	PROTECTIVE AS NEEDED



ALL DIMS IN

mm

EO® Edmund Optics®

TITLE

8" x 10", ITO COATED EMI SHIELDED PLASTIC WINDOW

DWG NO

83748

SHEET
1 OF 1