


NOTES:

1. RoHS: COMPLIANT

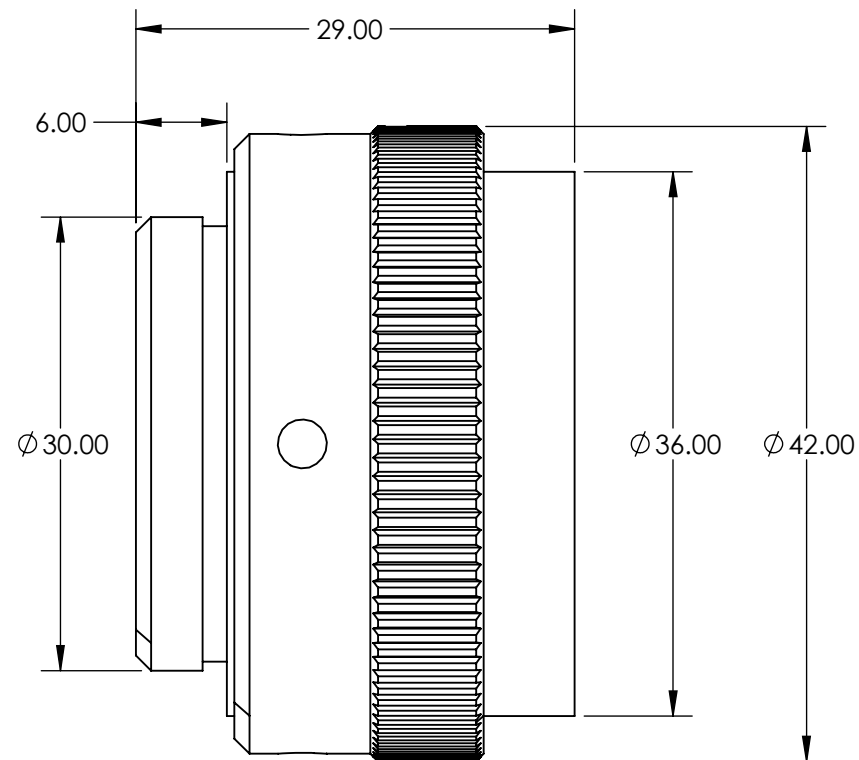

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY



	VALUE			TITLE	355 & 532nm, 8-12mm Dia. Input Beam, Focal Flat Top Beam Shaper Focal πShaper_NUV_Q 10	
DESIGN WAVELENGTH (nm)	355 & 532					
INPUT DIAMETER, 1/e ² (mm)	8 - 12	ALL DIMS IN	mm	DWG NO	12240	SHEET 1 OF 1
WAVELENGTH RANGE (nm)	335 - 560					