
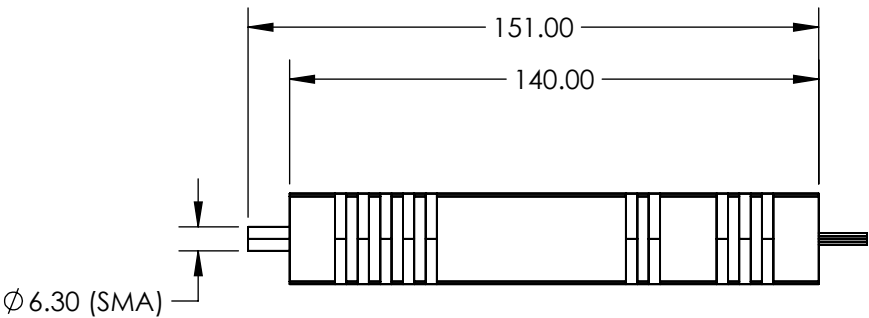
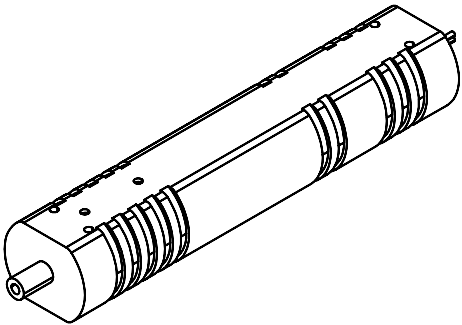


 
FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING

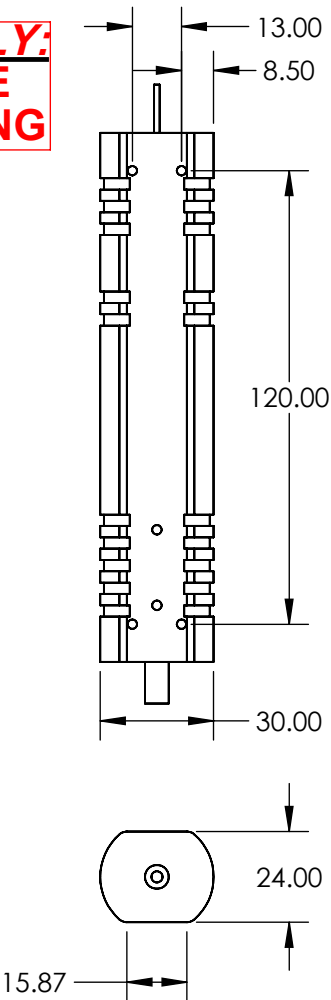

	VALUE
WAVELENGTH (nm)	808
OUTPUT POWER	50
COLOR	INFRARED
LASER CLASS	CLASS IIIB
OPERATING TEMPERATURE (°C)	1 - 10
OPERATING VOLTAGE (V)	+15 to +30
SPATIAL MODE	5.0
LASER TYPE	FIBER-COUPLED
CONNECTOR	DIODE
LENGTH OF FIBER (m)	1

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

EO[®] Edmund Optics[®]

THIRD ANGLE PROJECTION 		TITLE	50mW, 808nm Fiber-Coupled Laser Module	
ALL DIMS IN	mm	DWG NO	19484	SHEET 1 OF 1