

[Tous les Produits](#) / [Sources Lumineuses et Éclairages](#) / [Éclairages pour la Vision Industrielle](#) / [Barres Lumineuses](#)

Barres Lumineuses Infrarouge (IR) CCS See More by [CCS](#)



- Options de longueur d'onde de 850 ou 940 nm
- Boîtier compact et léger
- Configurations à une ou quatre barres disponibles

Spécifications

Caractéristiques du produit

Type d'Éclairage:	LED Illuminator	Fabricant:	CCS
Géométrie:	Bar Light	Mode d'Éclairage:	Constant

Propriétés optiques

Couleur:	IR
----------	----

Connectivité matérielle & interfaçage

Tension d'Entrée (V):	24
Alimentation d'Énergie:	Power Supply Required and Sold Separately: USA: #73-491 Europe: #73-491 Japan: #89-513 Korea: #33-773 China: #73-491

Informations techniques

Imaging the foreign materials in disinfectant product



Workpiece




Disinfectant product

Visible light Flat Light



It is difficult to check the inside with visible light imaging.

LFL series

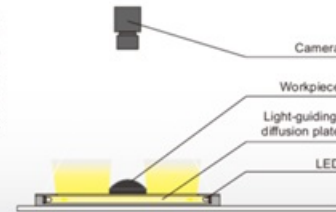

Infrared LFL-100IR940



Imaging with infrared light penetrates the liquid and captures the foreign materials.

* This workpiece was processed by CCS for sample imaging.

Produits

Dimensions (mm)	Couleur	Longueur d'Onde (nm)	Numéro de Stock	Prix	Achat
W 52 mm x D 17.2 mm x H 20 mm	IR	850.00	#21-843	€440,00	1 In Stock
W 52 mm x D 17.2 mm x H 20 mm	IR	940.00	#21-844	€405,00	3 In Stock
W 86 mm x D 28.8 mm x H 18 mm	IR	850.00	#21-845	€820,00	1 In Stock
W 86 mm x D 28.8 mm x H 18 mm	IR	940.00	#21-846	€820,00	1 In Stock
W 148 mm x D 148 mm x H 30.2mm	IR	850.00	#21-847	€2.885,00	2 In Stock
W 148 mm x D 148 mm x H 30.2mm	IR	940.00	#21-848	€2.885,00	1 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Téléphone: 1-800-363-1992 :

www.edmundoptics.com