


[Afficher tous les 12 produits de la même famille.](#)

**TECHSPEC®** Platine Inclinée Métrique Micromètre, 125mm

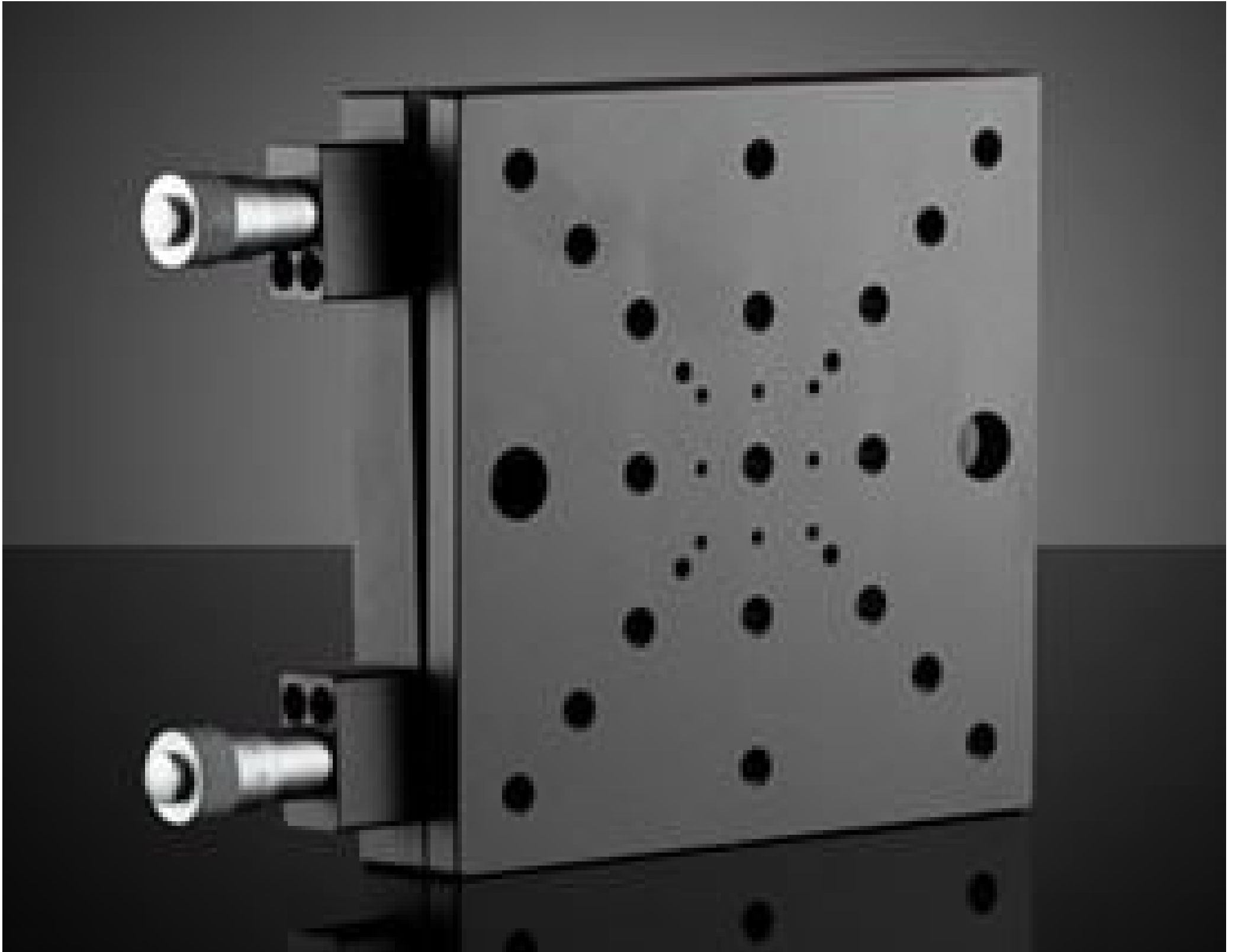

125mm Micrometer Tilt Stage

Stock **#66-555** **5 In Stock**

⊖ 1 ⊕ €665<sup>00</sup>

**AJOUTER AU PANIER**

Prix sur Quantité	
Qté 1-2	€665,00 prix unitaire
Qté 3+	€580,50 prix unitaire
Need More?	<a href="#">Demande de Devis</a>

ⓘ Les prix sont indiqués hors TVA et droits applicables.

Espace téléchargement

**Caractéristiques du produit**

Metric **Type:**

**Propriétés physiques et mécaniques**

Tip-Tilt **Type de Mouvement:**

125 x 125 **Taille de Plateau (mm):**

Course (°):  
±2

Construction:  
Aluminium Stage

Capacité de Charge (kg):  
4

Résolution (arcsec):  
24

Taille de Plateau (pouces):  
4.92 x 4.92

Poids (kg):  
0.8

## Connectivité matérielle & interfaçage

Mécanisme:  
Metric Micrometer

## Filetage & montage

Filetage:  
(19) M6 x 1, (4) M3 x 0.5, (8) M2 x 0.4

## Conformité réglementaire

RoHS 2015:  
[Dispensé](#)

Certificate of Conformance:  
[Visionner](#)

REACH 241:  
[Contains SVHC\(s\)](#)

## Description produit

- Versions métriques et impériales disponibles
- Contrôle de l'inclinaison dans deux axes (mouvement cinématique)
- Micromètre de précision
- Conçus pour s'intégrer avec d'autres Platines TECHSPEC®

Nos Platines d'Inclinaison TECHSPEC® sont disponibles en quatre formats de platines différents, allant de 30 à 70 mm carré. Chaque taille est proposée en version métrique ou impériale et dispose d'un mouvement micrométrique de précision qui assure la répétabilité du mouvement. Chaque platine est conçue pour s'intégrer aux composants TECHSPEC®, ce qui améliore encore la flexibilité et permet à l'utilisateur de créer un nombre illimité d'axes dans différentes configurations. Les Platines d'Inclinaison TECHSPEC sont idéales pour contrôler l'inclinaison des optiques et tiges de montage. Une [platine adaptatrice inférieure](#), vendue séparément, est nécessaire pour monter les platines de 30 mm et 40 mm à une table de laboratoire.

## Informations techniques

Bottom Stage	Top Stage																						
	30mm Linear Dovetail	30mm Linear	30mm Vertical	30mm Tip/Tilt	30mm Goniometer	30mm Rotary	40mm Linear Dovetail	40mm Linear	40mm Vertical	40mm Tip/Tilt	40mm Goniometer	40mm Rotary	65mm Linear Dovetail	65mm Linear	70mm Vertical	70mm Tip/Tilt	70mm Goniometer	70mm Rotary	125mm Linear	125mm Vertical	125mm Tip/Tilt	125mm Rotary	
30mm Linear Dovetail	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
30mm Linear	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
30mm Vertical	Compatible	Not Applicable	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
30mm Tip/Tilt	Compatible	Not Applicable	Not Applicable	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
30mm Goniometer	Compatible	Not Applicable	Not Applicable	Not Applicable	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
30mm Rotary	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
40mm Linear Dovetail	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
40mm Linear	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
40mm Vertical	Compatible	Not Applicable	Compatible	Not Applicable	Not Applicable	Not Applicable	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
40mm Tip/Tilt	Compatible	Not Applicable	Not Applicable	Compatible	Not Applicable	Not Applicable	Compatible	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
40mm Goniometer	Compatible	Not Applicable	Not Applicable	Not Applicable	Compatible	Not Applicable	Compatible	Compatible	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
40mm Rotary	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
65mm Linear Dovetail	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
70mm Linear	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
70mm Vertical	Compatible	Not Applicable	Compatible	Not Applicable	Not Applicable	Not Applicable	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
70mm Tip/Tilt	Compatible	Not Applicable	Not Applicable	Compatible	Not Applicable	Not Applicable	Compatible	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Compatible	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
70mm Goniometer	Compatible	Not Applicable	Not Applicable	Not Applicable	Compatible	Not Applicable	Compatible	Compatible	Compatible	Compatible	Compatible	Not Applicable	Compatible	Compatible	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
70mm Rotary	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
125mm Linear	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
125mm Vertical	Compatible	Not Applicable	Compatible	Not Applicable	Not Applicable	Not Applicable	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
125mm Tip/Tilt	Compatible	Not Applicable	Not Applicable	Compatible	Not Applicable	Not Applicable	Compatible	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Compatible	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable
125mm Rotary	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Compatible	Not Applicable	Not Applicable	Not Applicable	Not Applicable	Not Applicable