

1° Commercial Grade Wedge Prism



Stock **#27-676** FIN DE SÉRIE **4 In Stock**

-

1

+

€24^{,95}

AJOUTER AU PANIER

Prix sur Quantité	
Qté 1+	€24,95 prix unitaire
Need More?	Demande de Devis

ⓘ

 Les prix sont indiqués hors TVA et droits applicables.

Espace téléchargement

SPÉCIFICATIONS

Caractéristiques du produit

Type:

Wedge Prism

Propriétés physiques et mécaniques

Diamètre (mm):

25.00 ±0.1


3.00	Épaisseur (mm):
56'0"	Angle de Bord (arcmin):
Propriétés optiques	
MgF ₂ (400-700nm)	Traitement:
N-BK7	Substrat: ☐
1.00	Tolérance Angulaire (arcmin):
1λ	Précision de Surface:
Beam Deviation	Orientation de l'Image:
R _{avg} ≤ 1.75% @ 400 - 700nm	Spécification du Traitement:
1.74	Puissance (Dioptres):
1°	Angle de Bord (°):
Conformité réglementaire	
Visionner	Certificate of Conformance:

DESCRIPTION PRODUIT

- Feature Standard Designs and Specifications
- Ideal for Beam Steering
- For More Options, View Precision Quality [Wedge Prisms](#)

Wedge prisms can be used individually to deviate a laser beam a set angle, or two wedge prisms can be used together as an anamorphic pair. Commercial Grade Wedge Prisms offer commercial quality, at an affordable price.

INFORMATIONS TECHNIQUES

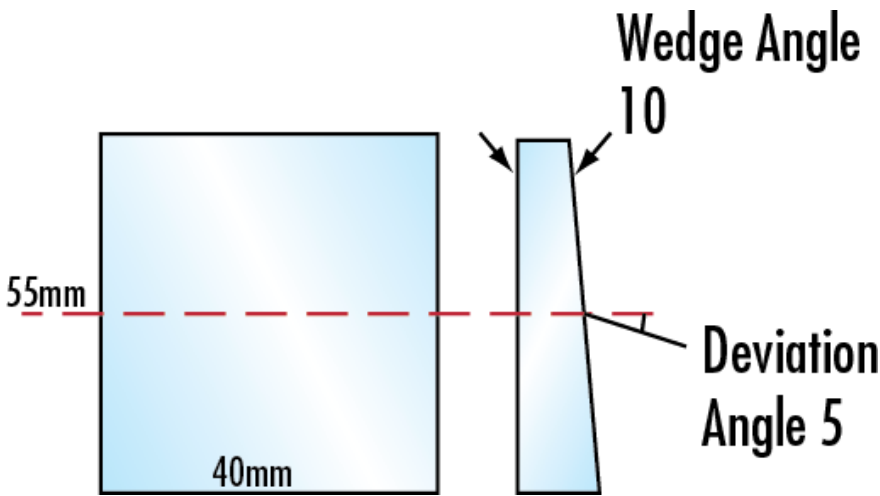

COATING CURVES