


In order to provide more accurate inventory information, please select your shipping country.

Sélectionner votre Pays/Région:

European Union

SUBMIT

See More by [ISP Optics](#)

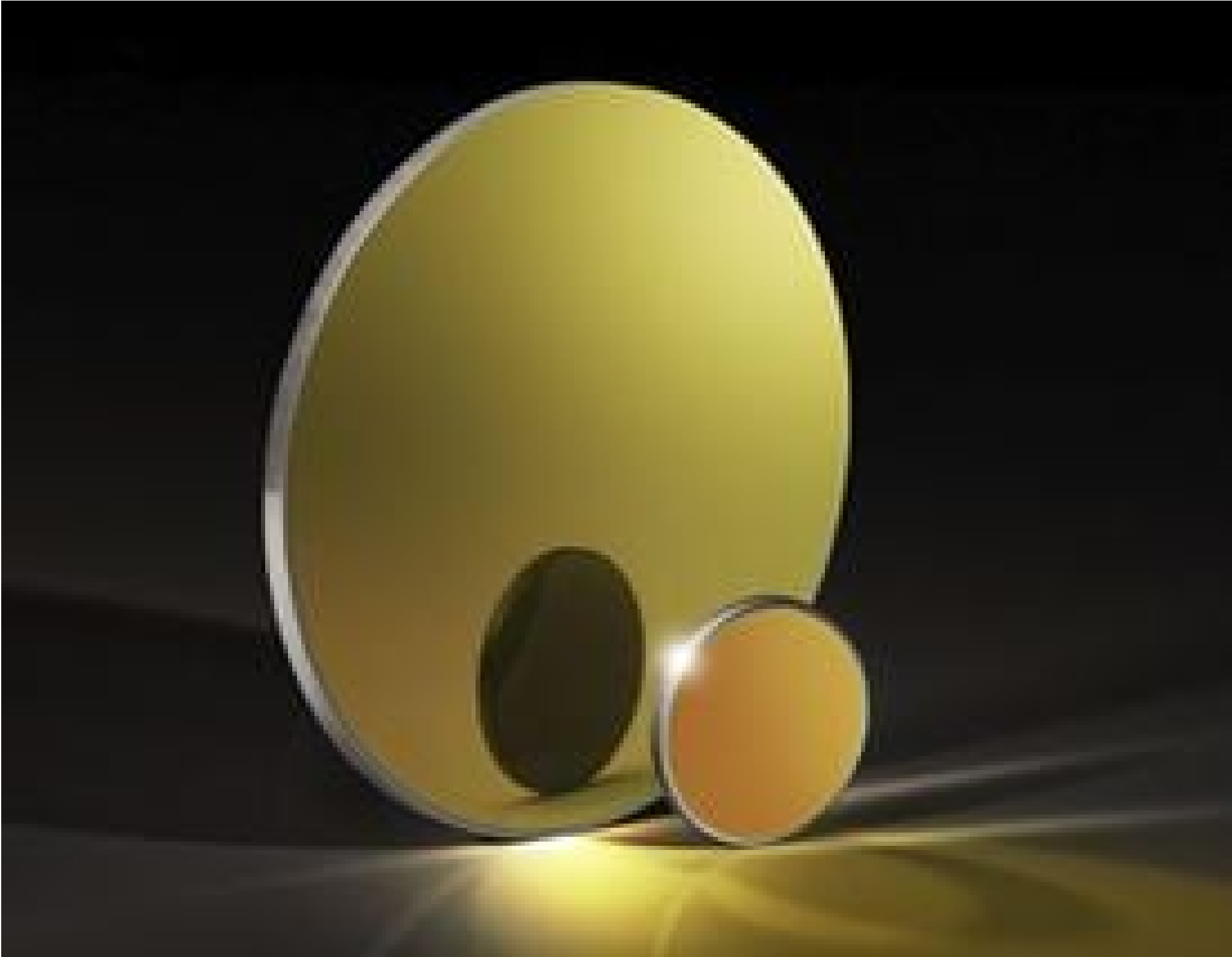

Diamond-Like Carbon (DLC) Coated Silicon Windows

Stock #16-816

3-4 JOURS



1



€292,50

AJOUTER AU PANIER

Qté 1+

€292,50

Prix sur Quantité

[Demande de Devis](#)

Les prix sont indiqués hors TVA et droits applicables.

Espace téléchargement



Biseau:
Protective as needed

Ouverture Utile (%):
85

Ouverture Utile CA (mm):
21.59

Diamètre (mm): 25.40 +0.00/-0.13
Épaisseur (mm): 2.00 ±0.13
Traitement: S1: DLC Coating S2: BBAR (3000-5000nm)
Spécification du Traitement: AR: R _{avg} ≤0.5% @ 3000 - 5000nm
Bords: Fine Ground
Dureté de Knoop (kg/mm²): 1150
Parallélisme (arcmin): <3
Substrat: Silicon (Si)
Planéité de Surface (P-V): λ/10 @ 10.6µm
Qualité de Surface: 40-20
Type: Protective Window
Gamme de Longueur d'Onde (nm): 3000 - 5000
Coating Abrasion: AR: Moderate, per MIL-C-48497C DLC: Severe, per MIL-C-48497C
Coating Adhesion: AR: per MIL-C-48497C DLC: per MIL-C-48497C
Coating Humidity: AR: 24 Hours per MIL-C-48497C DLC: 24 Hours per MIL-C-48497C
Coating Salt Solubility: AR: N/A DLC: ≥24 Hours Immersion per MIL-C-675C
Coating Salt Spray: AR: N/A ≥72 Hours per MIL-C-675
Coating Solubility and Cleaning: AR: per MIL-C-48497 DLC: per MIL-C-48497
Coating Temperature (°F): AR: -80 to +160 per MIL-C-48497C DLC: -80 to +160 per MIL-C-48497C
Coating Wiper Durability: AR: N/A DLC: ≥1,000 Wipes of Sand/Slurry per TS-1888
Remarque: Arrow on substrate edge points towards DLC coated surface
Numéro de Modèle: DLC35-SI-W-25-2

Conformité réglementaire

RoHS 2015: Conforme
Certificate of Conformance: Visionner