


In order to provide more accurate inventory information, please select your shipping country:

Sélectionner votre Pays/Région: European Union

SUBMIT

TECHSPEC® Polariseur Lineaire (XP42-70), 600 x 900 mm

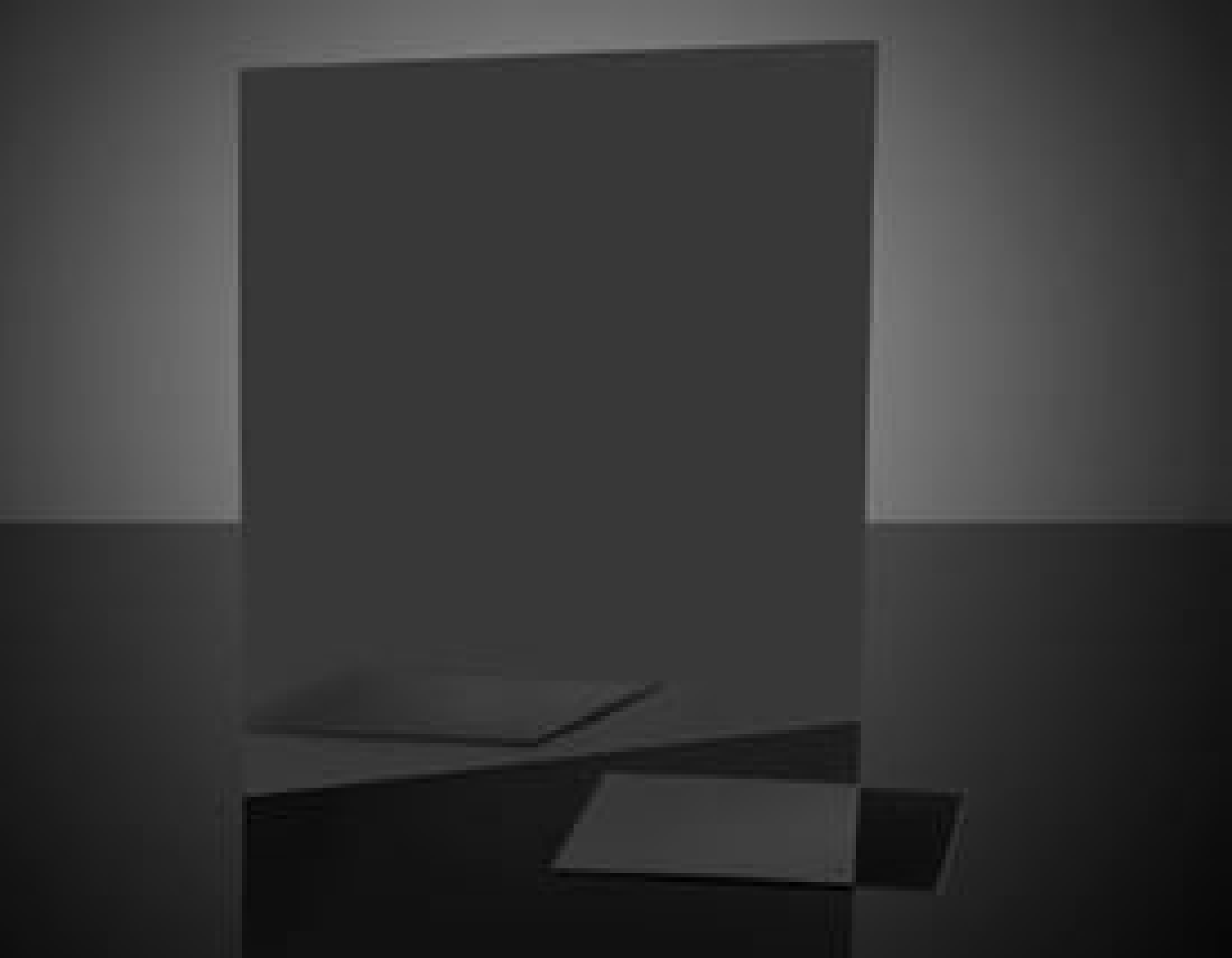

Stock #19-950 CONTACT

1 €360,00

AJOUTER AU PANIER

Qté 1+

€360,00

Prix sur Quantité

[Demande de Devis](#)

Les prix sont indiqués hors TVA et droits applicables.

Espace téléchargement

Rapport d'Extinction:

up to 9000:1 (nominal at 555nm)

Substrat: ☐

[Polymer Film XP42 on 0.5 mm PMMA](#)

Température d'Utilisation (°C):

-10 to +60

Dimensions (mm):

600.0 x900.0

Épaisseur (mm):

0.71

Tolérance Épaisseur (mm): ±0.15
Transmission (%): Single: 42 ±2 Parallel: 36.4 Crossed: <0.004 (nominal at 555nm)
Type: Linear Polarizer
Tolérance Dimensionelle (mm): ±3.0
Construction: Polarizing Film on PMMA
Remarque: Polarization axis can be identified as follows: Circular Parts - Parallel to direction of notch on polarizer Square Parts - Parallel to mark on protective film Rectangular Parts - Parallel to first listed dimension
Gamme de Longueur d'Onde (nm): 400 - 700
Efficacité de la polarisation (%): >99.98 (nominal at 555nm)
Transmission Variance after 1000 Hours (%): <±5
Humidité d'Utilisation: ≤80% (no condensation)
#Sorting: 66.00

Conformité réglementaire

RoHS 2015: Conforme
Certificate of Conformance: Visionner
Reach 235: Conforme